

# Technical data sheet

## Trunking connector and joint cover

Item number: 6113212



Joint cover for the bases of the Rapid 45 device installation trunking to hide cut edges and provide a perfect connection of the trunking segments. The joint covers are attached. Suitable for trunking width 130 mm.



Polycarbonate/Acrylnitrile-butadiene-styrene

### Master data

|                     |                                              |
|---------------------|----------------------------------------------|
| Item number         | 6113212                                      |
| Description 1       | Joint cover                                  |
| Description 2       | for Rapid 45-2 130                           |
| Manufacturer        | OBO                                          |
| Dimension           | 133x55x15                                    |
| Colour              | Light grey; RAL 7035                         |
| Material            | Polycarbonate/Acrylnitrile-butadiene-styrene |
| Smallest sales unit | 6                                            |
| Unit of quantity    | Piece                                        |
| Weight              | 0.707 kg                                     |
| Weight unit         | kg/100 pc.                                   |


# Technical data sheet

## Trunking connector and joint cover

Item number: 6113212



### Dimensions

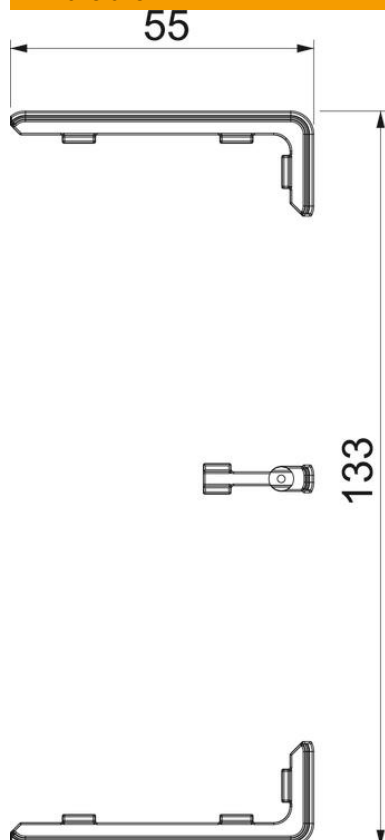

|        |       |
|--------|-------|
| Length | 15 mm |
| Width  | 55 mm |
| Height | 17 mm |

### Technical data

|                                   |                         |
|-----------------------------------|-------------------------|
| Version for                       | Trunking cut cover      |
| Fastening type                    | Slide (before mounting) |
| Shape                             | Symmetrical             |
| for duct width                    | 130 mm                  |
| for trunking height               | 53 mm                   |
| Halogen-free                      | yes                     |
| Cover width                       | 45 mm                   |
| Protection rating                 | IP40                    |
| Protection rating IK code         | IK08                    |
| Permitted temperature range, max. | 60 °C                   |
| Permitted temperature range, min. | -15 °C                  |