

Technical data sheet

Coupling GK-KUP

Item number: 6274650



Coupling as trunking connector for tight connection of the trunking sections. A coupling pair is included and pre-mounted for each stock length.



Acrylonitrile butadiene styrene

Master data		
Item number	6274650	
Description 1	Coupling	
Description 2	for GK	
Manufacturer	OBO	
Dimension	64x90mm	
Colour	Light grey; RAL 7035	
Material	Acrylonitrile butadiene styrene	
Smallest sales unit	1	
Unit of quantity	Packaging unit	
Weight	2.14 kg	
Weight unit	kg/100 PUs	

Technical data sheet

Coupling GK-KUP


Item number: 6274650



Dimensions



Length	89.5 mm
Width	64 mm

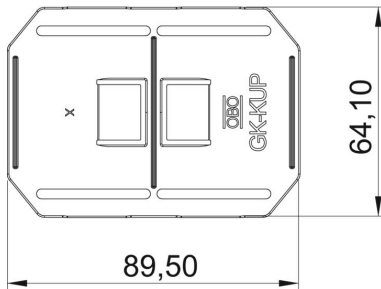

Technical data

Version for	Universal
Type	coupling
Halogen-free	yes
Trunking depth	70 mm
With equipotential bonding	no
Protection rating	IP30
Protection rating IK code	IK08
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-15 °C