


Technical data sheet

External corner cover, smooth

Item number: 6274796



PVC external corner cover, smooth surface.

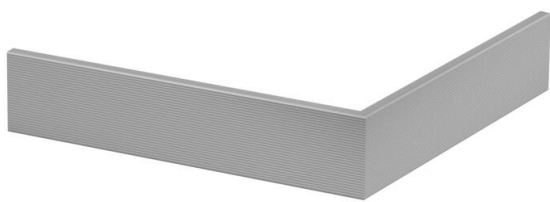

| Master data         |                         |
|---------------------|-------------------------|
| Item number         | 6274796                 |
| Description 1       | Cover                   |
| Description 2       | external corner, smooth |
| Manufacturer        | OBO                     |
| Colour              | Stone grey; RAL 7030    |
| Material            | Polyvinylchloride       |
| Smallest sales unit | 1                       |
| Unit of quantity    | Piece                   |
| Weight              | 9.5 kg                  |
| Weight unit         | kg/100 pc.              |


# Technical data sheet

## External corner cover, smooth

Item number: 6274796



### Dimensions

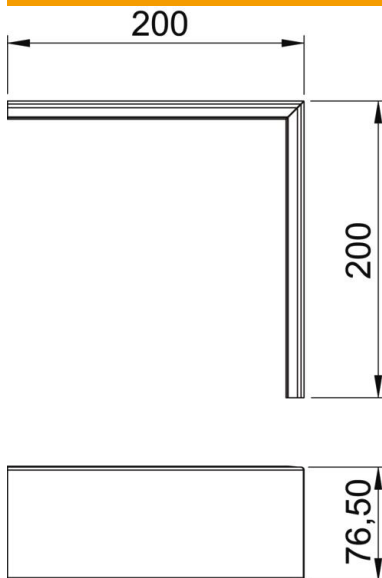

|        |         |
|--------|---------|
| Length | 200 mm  |
| Width  | 76.5 mm |
| Height | 12 mm   |

### Technical data

|                                   |                 |
|-----------------------------------|-----------------|
| Application                       | External corner |
| Halogen-free                      | no              |
| Cover mounting type               | Internal        |
| Protection rating                 | IP30            |
| Protective film                   | yes             |
| Protection rating IK code         | IK08            |
| Permitted temperature range, max. | 60 °C           |
| Permitted temperature range, min. | -15 °C          |