

Technical data sheet

Cover Rapid 80, opal, smooth

Item number: 6278690



Trunking cover for closing Rapid 80 GK (PVC), GS (steel) and GA (aluminium) device installation trunking as well as ISS service poles with a 76.5 mm system opening. The GK-OTGO cover is made from translucent but milky plastic (looking like cut glass) and is therefore suitable for integrating lighting in the trunking or service poles.



PC Polycarbonate

Master data

Item number	6278690
Type	GK-OTGO
Description 1	Cover
Description 2	smooth opal
Manufacturer	OBO
Dimension	80x2000mm
Colour	Transparent
Material	Polycarbonate
Smallest sales unit	2
Unit of quantity	Metre
Weight	21.8 kg
Weight unit	kg/100 m


Technical data sheet

Cover Rapid 80, opal, smooth

Item number: 6278690



Dimensions

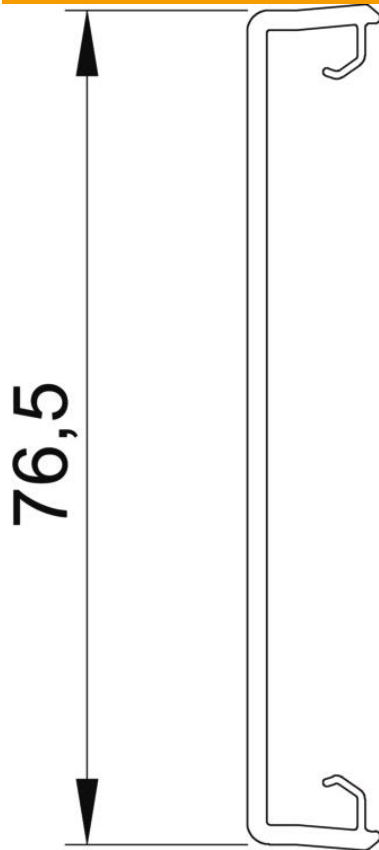

Length	2,000 mm
Width	76.5 mm
Height	12 mm

Technical data

Version for	Smooth
Halogen-free	no
Cover mounting type	Internal
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK08
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-15 °C