

Technical data sheet

Plastic trunking cover, smooth

Item number: 6278680



Smooth trunking cover, for closing device installation trunking with 76.5 mm system opening.



PVC

 Polyvinylchloride

Master data	
Item number	6278680
Description 1	Cover
Description 2	smooth
Manufacturer	OBO
Dimension	80x2000mm
Colour	Pure white; RAL 9010
Material	Polyvinylchloride
Smallest sales unit	2
Unit of quantity	Metre
Weight	27.5 kg
Weight unit	kg/100 m
CO Footprint (GWP) Cradle-to-Gate	0,4485 kg COe / 1 Meter


Technical data sheet

Plastic trunking cover, smooth

Item number: 6278680



Dimensions

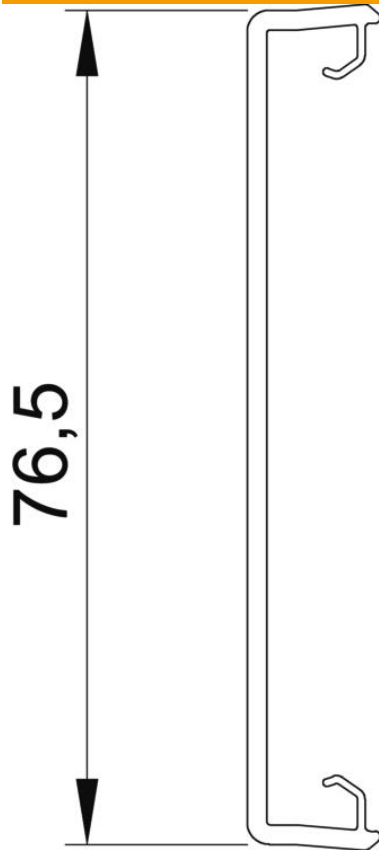

Length	2,000 mm
Width	76.5 mm
Height	12 mm

Technical data

Version for	Smooth
Cover mounting type	Internal
Protection rating	IP30
Protection rating IK code	IK08
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-15 °C