

# Technical data sheet

Flat angle cover, fluted

Item number: 6274590



Flat angle cover, fluted surface.



**PVC** Polyvinylchloride

| Master data         |                      |
|---------------------|----------------------|
| Item number         | 6274590              |
| Type                | GK-OTKFRW            |
| Description 1       | Cover                |
| Description 2       | flat angle, fluted   |
| Manufacturer        | OBO                  |
| Colour              | Pure white; RAL 9010 |
| Material            | Polyvinylchloride    |
| Smallest sales unit | 1                    |
| Unit of quantity    | Piece                |
| Weight              | 20 kg                |
| Weight unit         | kg/100 pc.           |


# Technical data sheet

## Flat angle cover, fluted

Item number: 6274590



### Dimensions

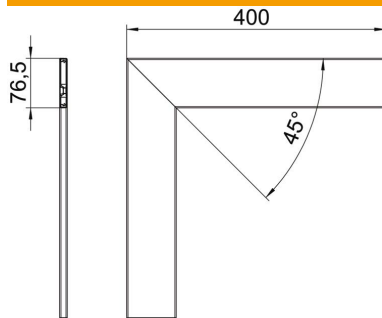

|        |         |
|--------|---------|
| Length | 400 mm  |
| Width  | 76.5 mm |

### Technical data

|                                   |          |
|-----------------------------------|----------|
| Version for                       | Profiled |
| Halogen-free                      | no       |
| Cover mounting type               | Internal |
| Protection rating                 | IP30     |
| Protective film                   | yes      |
| Protection rating IK code         | IK08     |
| Permitted temperature range, max. | 60 °C    |
| Permitted temperature range, min. | -15 °C   |