

Technical data sheet

Partition GK-TW70

Item number: 6274900



Partition for mounting in Rapid 80 GK, GA and Rapid IBIS device installation trunking or ISS service poles for installing cables of different voltage levels.



PVC Polyvinylchloride

Master data

Item number	6274900
Description 1	Partition
Description 2	for GK
Manufacturer	OBO
Dimension	70x2000mm
Colour	Light grey; RAL 7035
Material	Polyvinylchloride
Smallest sales unit	2
Unit of quantity	Metre
Weight	17.4 kg
Weight unit	kg/100 m


Technical data sheet

Partition GK-TW70

Item number: 6274900



Dimensions

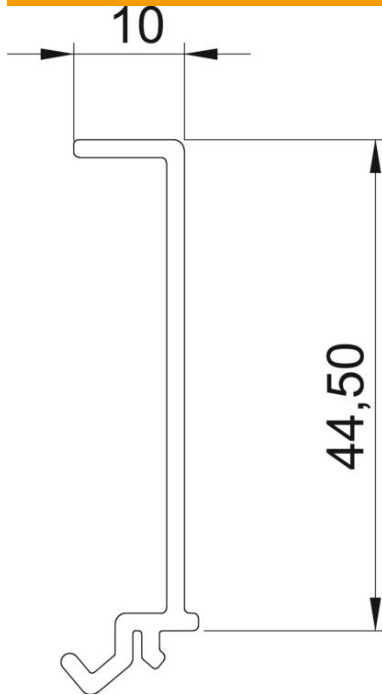

Length	2,000 mm
Width	44.5 mm
Height	10 mm

Technical data

Version for	Single
Fastening type	Plug-in
Suitable for duct depth	70
Halogen-free	no
Protection rating	IP30
Protection rating IK code	IK08
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-15 °C