


Technical data sheet

External corner cover, smooth

Item number: 6114230



PC/ABS external corner cover, smooth surface.

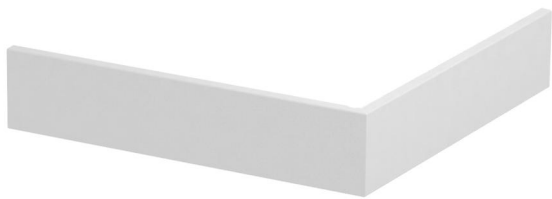

PC/ABS

Polycarbonate/Acrylnitrile-butadiene-styrene

Master data	
Item number	6114230
Description 1	Cover, halogen-free
Description 2	external corner, smooth
Manufacturer	OBO
Colour	Pure white; RAL 9010
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	1
Unit of quantity	Piece
Weight	7.5 kg
Weight unit	kg/100 pc.


Technical data sheet

External corner cover, smooth

Item number: 6114230



Dimensions

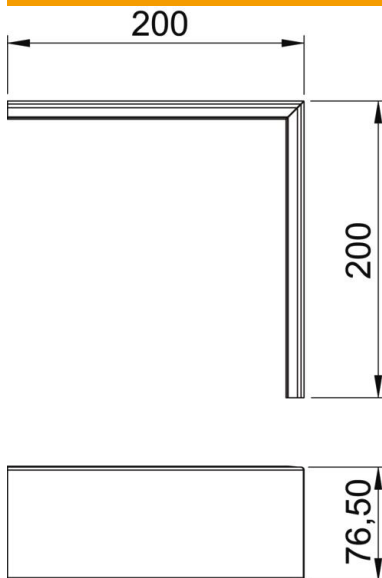

Length	200 mm
Width	76.5 mm
Height	12 mm

Technical data

Application	External corner
Halogen-free	yes
Cover mounting type	Internal
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK08
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-15 °C