

Technical data sheet

Flat angle cover, smooth

Item number: 6114250



Flat angle cover made of halogen-free PC/ABS.



Polycarbonate/Acrylnitrile-butadiene-styrene

Master data		
Item number	6114250	
Type	GKH-OTGFRW	
Description 1	Cover, halogen-free	
Description 2	flat angle, smooth	
Manufacturer	OBO	
Colour	Pure white; RAL 9010	
Material	Polycarbonate/Acrylnitrile-butadiene-styrene	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	13 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	1,2 kg CO2e / 1 Piece	


Technical data sheet

Flat angle cover, smooth

Item number: 6114250



Dimensions

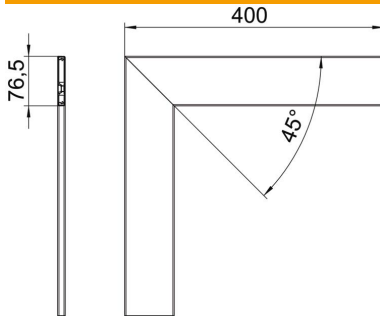

Length	400 mm
Width	76.5 mm
Height	12 mm

Technical data

Version for	Smooth
Halogen-free	yes
Cover mounting type	Internal
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK08
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-15 °C