


# Technical data sheet

## Mesh cable tray GR-Magic® 105 G

Item number: 6002404

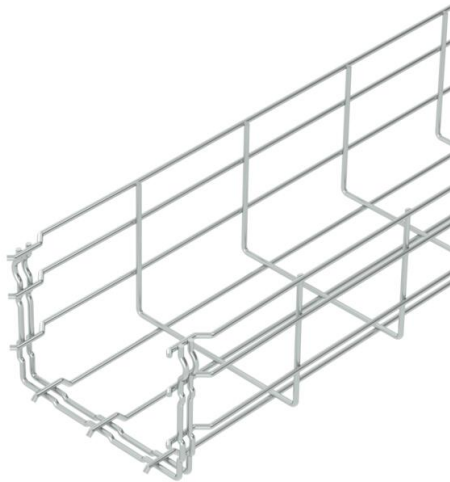

Mesh cable tray with shaped connector of side height 105 mm.  
No additional connection components are required for the mesh cable tray, it is simply interlocked. The grid width is 50 x 100 mm.  
Magnetic shield insulation without cover 15 dB, with cover 25 dB.



|    |                   |
|----|-------------------|
| St | Steel             |
| G  | Electrogalvanized |

### Master data

|                                    |                            |
|------------------------------------|----------------------------|
| Item number                        | 6002404                    |
| Type                               | GRM 105 150 G              |
| Description 1                      | Mesh cable tray GRM        |
| Manufacturer                       | OBO                        |
| Dimension                          | 105x150x3000               |
| Colour                             | zinc                       |
| Material                           | Steel                      |
| Surface                            | Electrogalvanized          |
| Surface standard                   | EN ISO 19598 / EN ISO 4042 |
| Smallest sales unit                | 3                          |
| Unit of quantity                   | Metre                      |
| Weight                             | 111.667 kg                 |
| Weight unit                        | kg/100 m                   |
| CO2 Footprint (GWP) Cradle-to-Gate | 2,0866 kg CO2e / 1 Meter   |



# Technical data sheet

## Mesh cable tray GR-Magic® 105 G

Item number: 6002404



### Dimensions

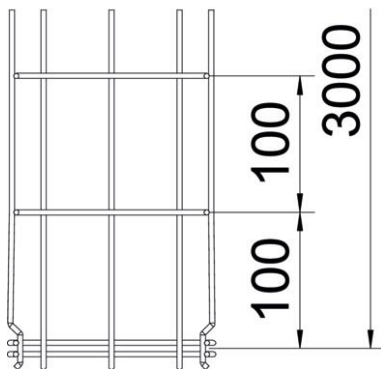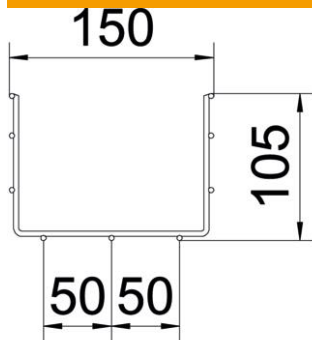

|             |          |
|-------------|----------|
| Length      | 3,000 mm |
| Width       | 150 mm   |
| Width       | 5.91 in  |
| Height      | 105 mm   |
| Height      | 4.13 in  |
| Dimension B | 150 mm   |
| Dimension H | 108 mm   |

### Technical data

|                                         |                       |
|-----------------------------------------|-----------------------|
| Connector version                       | Integrated connector  |
| Mounting system fastening type          | Floor Ceiling Wall    |
| Maintain electrical functions           | no                    |
| Integrated partition                    | Without               |
| Usable cross-section                    | 130 cm <sup>2</sup>   |
| Usable cross-section                    | 13000 mm <sup>2</sup> |
| Profile shape                           | U-shaped              |
| Rustproof steel, pickled                | no                    |
| Screwless connector                     | yes                   |
| Wide-span version                       | no                    |
| Load test type according to IEC 61537   | Type II               |
| Type of connector, cable support system | Click fastening       |

# Technical data sheet

## Mesh cable tray GR-Magic® 105 G

Item number: 6002404



### Loads

|                                   |           |
|-----------------------------------|-----------|
| Insertable support spacings, min. | 1 m       |
| Insertable support spacings, max. | 3 m       |
| Support spacing 1.0 m             | 0.8 kN/m  |
| Support spacing 1.5 m             | 0.55 kN/m |
| Support spacing 2.0 m             | 0.37 kN/m |
| Support spacing 2.5 m             | 0.27 kN/m |
| Support spacing 3.0 m             | 0.25 kN/m |