

Technical data sheet

Sheet steel external corner cover, 50 mm system opening

Item number: 6279890



Sheet steel external corner cover for the 50 mm system opening.



St Steel

Master data

Item number	6279890
Type	GS-OT50ARW
Description 1	Cover
Description 2	for external corner System 50
Manufacturer	OBO
Dimension	12x45x300
Colour	Pure white; RAL 9010
Material	Steel
Smallest sales unit	1
Unit of quantity	Piece
Weight	14.7 kg
Weight unit	kg/100 pc.


Technical data sheet

Sheet steel external corner cover, 50 mm system opening

Item number: 6279890



Dimensions

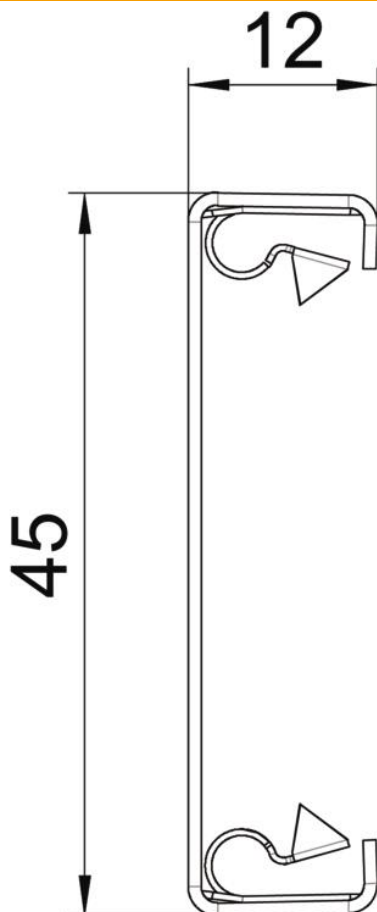

Length	300 mm
Width	45 mm
Height	12 mm

Technical data

Application	External corner
Halogen-free	yes
Cover mounting type	Internal
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK10
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C