

Technical data sheet

Trunking cover, sheet steel, 100 mm

Item number: 6286930



Sheet steel cover for closing the GS device installation trunking.
Sheet steel version.



St Steel

Master data

Item number	6286930
Type	GS-OTRW 100
Description 1	Cover
Description 2	for system opening 80
Manufacturer	OBO
Dimension	12x76,5x100
Colour	Pure white; RAL 9010
Material	Steel
Smallest sales unit	1
Unit of quantity	Piece
Weight	6.8 kg
Weight unit	kg/100 pc.


Technical data sheet

Trunking cover, sheet steel, 100 mm

Item number: 6286930



Dimensions

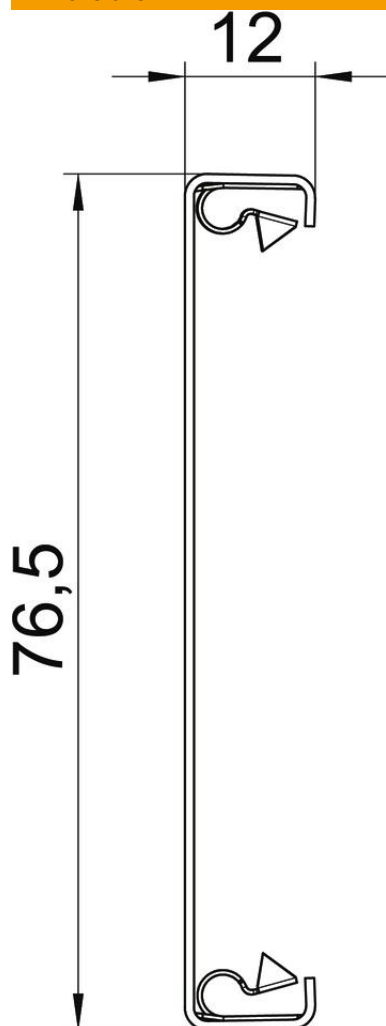

Length	100 mm
Width	76.5 mm
Height	12 mm

Technical data

Version for	Smooth
Base perforation	0
Halogen-free	yes
Cover mounting type	Internal
Protection rating	IP30
Protective film	no
Protection rating IK code	IK10
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C