

Technical data sheet

Partition GS-TW90

Item number: 6277095



Partition to divide the trunking for different voltage levels. Self-conducting contacting during mounting.




St	Steel
FS	Strip galvanized

Master data

Item number	6277095
Description 1	Partition
Description 2	for GS 90
Manufacturer	OBO
Dimension	24x73x2000
Colour	zinc
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	2
Unit of quantity	Metre
Weight	74.4 kg
Weight unit	kg/100 m

Dimensions

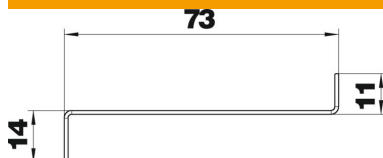

Length	2,000 mm
Width	24 mm
Height	73 mm

Technical data sheet

Partition GS-TW90

Item number: 6277095



Technical data

Version for	Single
Fastening type	Plug-in
Suitable for duct depth	90
Halogen-free	yes
Protection rating	IP30
Protection rating IK code	IK10
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C