

Technical data sheet

Joint connector A2

Item number: 6016642



Screwed version of joint connector for mesh cable trays.
Including screw of type FRS M6 x 20.
Figure: Positioning and quantity of mesh cable tray connectors.

50–150 mm = 2 units

200–300 mm = 3 units

400–450 mm = 4 units

500–600 mm = 5 units



A2 Stainless steel

2B Bright, treated

Master data

| | |
|------------------------------------|-------------------------|
| Item number | 6016642 |
| Type | GSV 34 A2 |
| Description 1 | Joint connector |
| Description 2 | for mesh cable tray |
| Manufacturer | OBO |
| Colour | stainless steel |
| Material | Stainless steel |
| Surface | Bright, treated |
| Surface standard | |
| Smallest sales unit | 20 |
| Unit of quantity | Piece |
| Weight | 3.1 kg |
| Weight unit | kg/100 pc. |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,233 kg CO2e / 1 Piece |


Technical data sheet

Joint connector A2

Item number: 6016642



Dimensions

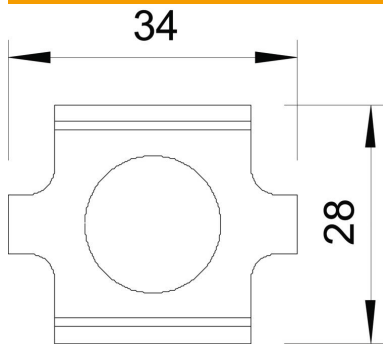

| | |
|-----------|-----------|
| Dimension | 34 x 27,5 |
| Length | 34 mm |
| Width | 29 mm |
| Width | 1.14 in |
| Height | 24 mm |
| Height | 0.94 in |

Technical data

| | |
|---|--------------------|
| Version for | Straight connector |
| Maintain electrical functions | no |
| Suitable for mesh cable tray | yes |
| Suitable for cable ladder | no |
| Suitable for cable tray | no |
| Adjustable connector, horizontal | no |
| Articulated connector, vertical | no |
| Suitable for mesh cable tray wire, max. | 4.9 mm |
| Suitable for mesh cable tray wire, min. | 3.9 mm |
| Rustproof steel, pickled | yes |
| Connection type | Screw connector |