

# Technical data sheet

## Joint connector A4

Item number: 6016648



Screwed version of joint connector for mesh cable trays.  
Including screw of type FRS M6 x 20.  
Figure: Positioning and quantity of mesh cable tray connectors.



50–150 mm = 2 units

200–300 mm = 3 units

400–450 mm = 4 units

500–600 mm = 5 units



**A4** Stainless steel

**2B** Bright, treated

### Master data

Item number	6016648
Description 1	Joint connector
Description 2	for mesh cable tray
Manufacturer	OBO
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	20
Unit of quantity	Piece
Weight	3 kg
Weight unit	kg/100 pc.


# Technical data sheet

## Joint connector A4

Item number: 6016648



### Dimensions

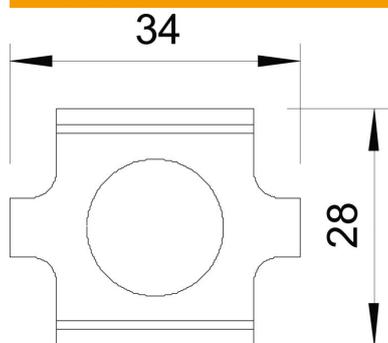

Dimension	28 x 34
Length	34 mm
Width	29 mm
Width	1.14 in
Height	24 mm
Height	0.94 in

### Technical data

Version for	Straight connector
Maintain electrical functions	no
Suitable for mesh cable tray	yes
Suitable for cable ladder	no
Suitable for cable tray	no
Adjustable connector, horizontal	no
Articulated connector, vertical	no
Suitable for mesh cable tray wire, max.	4.9 mm
Suitable for mesh cable tray wire, min.	3.9 mm
Rustproof steel, pickled	yes
Connection type	Screw connector