


Technical data sheet

Hexagonal bolt DIN 933 V2A

Item number: 3156040



Hexagonal bolt according to DIN 933 with metric thread.

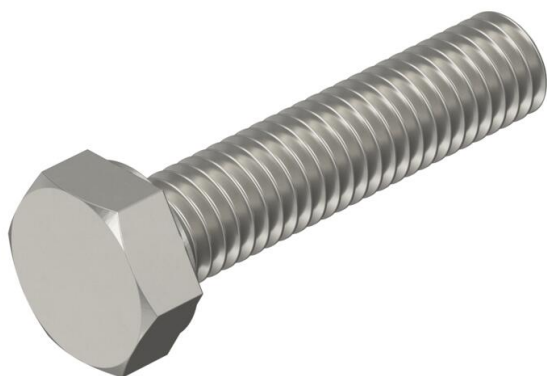

A2	Stainless steel
2B	Bright, treated

Master data

Item number	3156040
Type	HHS M10x45 A2
Description 1	Hexagonal screw
Description 2	fully threaded
Manufacturer	OBO
Dimension	M10x45mm
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	50
Unit of quantity	Piece
Weight	3.37 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1626 kg COe / 1 Piece


Technical data sheet

Hexagonal bolt DIN 933 V2A

Item number: 3156040



Dimensions

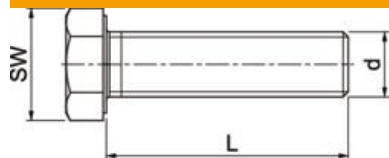

Length	45 mm
Dimension D	10 mm
Dimension d	10 mm
Dimension L	45 mm

Technical data

Thread	M10
Thread metric	10
Thread type	Metric
Thread length	45 mm
Head shape	Hexagonal
With flange	no
With nut	no
With washer	no
WAF	17
Screw system	Hexagonal
Self-locking	no
Full thread	yes
Left thread	no