

Technical data sheet

Hexagonal bolt DIN 933 A4

Item number: 3156034



Hexagonal bolt M10 x 50 mm




A4	Stainless steel
2B	Bright, treated

Master data

Item number	3156034
Type	HHS M10x50 A4
Description 1	Hexagonal screw
Manufacturer	OBO
Dimension	M10x50mm
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	50
Unit of quantity	Piece
Weight	3.62 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1746 kg COe / 1 Piece

Dimensions

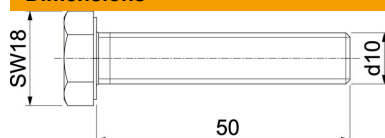

Length	50 mm
Dimension d	10 mm
Dimension L	50 mm

Technical data sheet

Hexagonal bolt DIN 933 A4

Item number: 3156034



Technical data

Thread	M10
Thread metric	10
Thread type	Metric
Thread length	50 mm
Head shape	Hexagonal
With flange	no
With nut	no
With washer	no
WAF	17
Screw system	Hexagonal
Self-locking	no
Full thread	yes
Left thread	no