


Technical data sheet

Hexagonal bolt DIN 933 A4

Item number: 3156029



Hexagonal bolt M12 x 40 mm

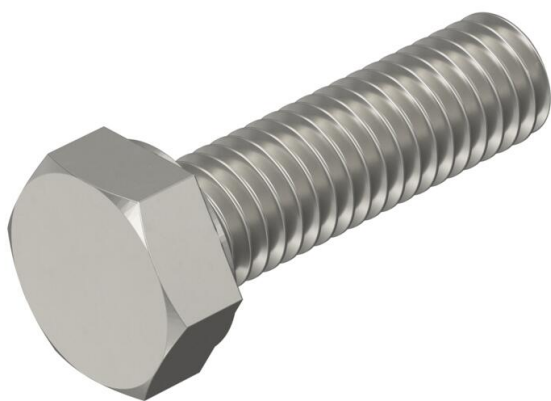

A4 Stainless steel

2B Bright, treated

Master data

Item number	3156029
Type	HHS M12x40 A4
Description 1	Hexagonal screw
Description 2	for profile rail MS-41
Manufacturer	OBO
Dimension	M12x40mm
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	50
Unit of quantity	Piece
Weight	4.74 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,228 kg COe / 1 Piece


Technical data sheet

Hexagonal bolt DIN 933 A4

Item number: 3156029



Dimensions

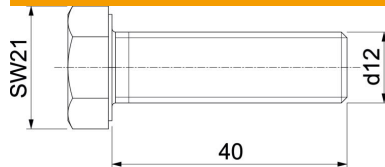

Length	40 mm
Dimension d	12 mm
Dimension L	40 mm

Technical data

Resistance grade	min. 70
Thread	M12
Thread metric	12
Thread type	Metric
Thread length	40 mm
Head shape	Hexagonal
With flange	no
With nut	no
With washer	no
WAF	19
Screw system	Hexagonal
Self-locking	no
Full thread	yes
Left thread	no