


# Technical data sheet

## Hexagonal bolt DIN 933 A5

Item number: 3156067



Hexagonal bolt M12x40

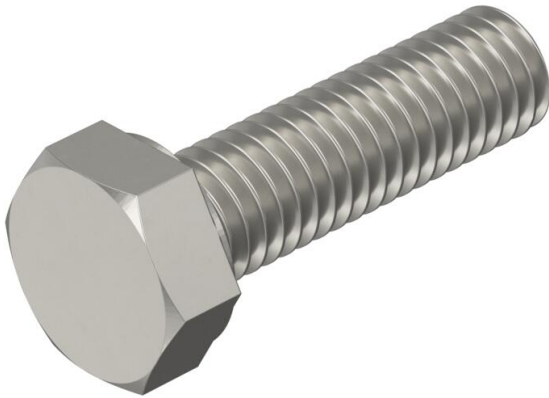


A5 Stainless steel

### Master data

|                                    |                         |
|------------------------------------|-------------------------|
| Item number                        | 3156067                 |
| Type                               | HHS M12x40 A5           |
| Description 1                      | Hexagonal screw         |
| Manufacturer                       | OBO                     |
| Dimension                          | M12x40mm                |
| Material                           | Stainless steel         |
| Smallest sales unit                | 50                      |
| Unit of quantity                   | Piece                   |
| Weight                             | 4.49 kg                 |
| Weight unit                        | kg/100 pc.              |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,2156 kg COe / 1 Piece |

### Dimensions

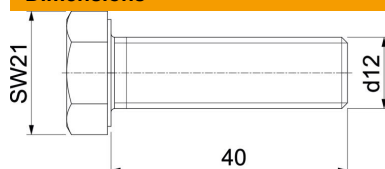

|             |       |
|-------------|-------|
| Length      | 40 mm |
| Dimension d | 12 mm |
| Dimension L | 40 mm |

# Technical data sheet

## Hexagonal bolt DIN 933 A5

Item number: 3156067



### Technical data

|               |           |
|---------------|-----------|
| Thread        | M12       |
| Thread metric | 12        |
| Thread type   | Metric    |
| Thread length | 40 mm     |
| Head shape    | Hexagonal |
| With flange   | no        |
| With nut      | no        |
| With washer   | no        |
| WAF           | 19        |
| Screw system  | Hexagonal |
| Self-locking  | no        |
| Full thread   | yes       |
| Left thread   | no        |