


Technical data sheet

Hexagonal bolt DIN 933 A4

Item number: 3156037



Hexagonal bolt M12 x 50 mm

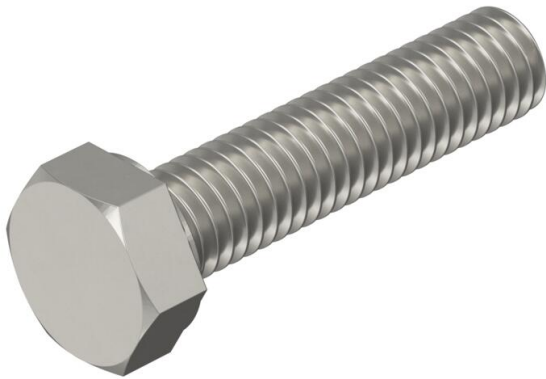


A4	Stainless steel
2B	Bright, treated

Master data

Item number	3156037
Type	HHS M12x50 A4
Description 1	Hexagonal screw
Manufacturer	OBO
Dimension	M12x50mm
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	50
Unit of quantity	Piece
Weight	5.2 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,2501 kg COe / 1 Piece

Dimensions

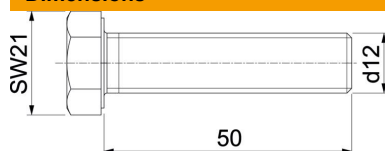

Length	50 mm
Dimension d	12 mm
Dimension L	50 mm

Technical data sheet

Hexagonal bolt DIN 933 A4

Item number: 3156037



Technical data

Thread	M12
Thread metric	12
Thread type	Metric
Thread length	50 mm
Head shape	Hexagonal
With flange	no
With nut	no
With washer	no
WAF	19
Screw system	Hexagonal
Self-locking	no
Full thread	yes
Left thread	no