


# Technical data sheet

## Hexagonal bolt DIN 933 V2A

Item number: 3156044



Hexagonal bolt according to DIN 933 with metric thread.

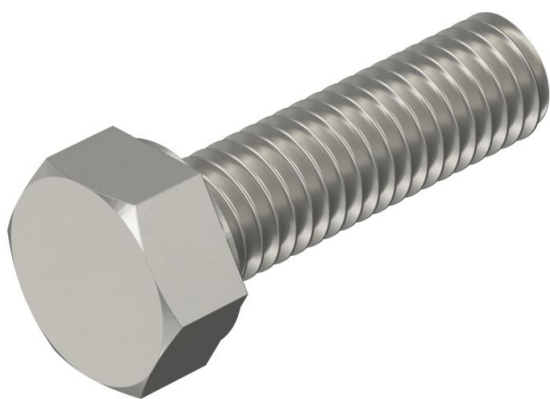

A2	Stainless steel
2B	Bright, treated

### Master data

Item number	3156044
Type	HHS M16x50 A2
Description 1	Hexagonal screw
Description 2	fully threaded
Manufacturer	OBO
Dimension	M16x50mm
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	50
Unit of quantity	Piece
Weight	10.3 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,4909 kg COe / 1 Piece


# Technical data sheet

## Hexagonal bolt DIN 933 V2A



Item number: 3156044

### Dimensions

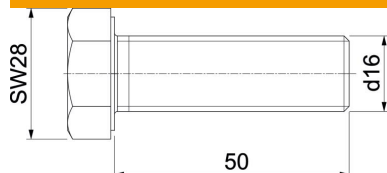

Length	50 mm
Dimension D	16 mm
Dimension d	16 mm
Dimension L	50 mm

### Technical data

Thread	M16
Thread metric	16
Thread type	Metric
Thread length	50 mm
Head shape	Hexagonal
With flange	no
With nut	no
With washer	no
WAF	24
Screw system	Hexagonal
Self-locking	no
Full thread	yes
Left thread	no