

Technical data sheet

Hexagonal nut DIN 934 V2A

Item number: 3397106



Hexagonal nut to DIN 934 with metric thread.



A2 Stainless steel

2B Bright, treated

Master data

Item number	3397106
Type	HN M10 A2
Description 1	Hexagonal nut
Manufacturer	OBO
Dimension	M10
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	100
Unit of quantity	Piece
Weight	1.043 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,0502 kg COe / 1 Piece


Technical data sheet

Hexagonal nut DIN 934 V2A

Item number: 3397106



Dimensions

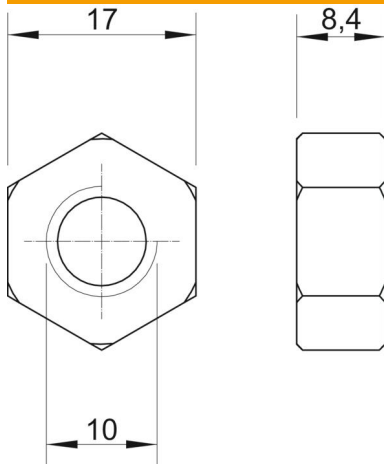

Dimension d	10 mm
Dimension h	8.4 mm

Technical data

Thread	M10
Thread metric	10
Thread type	Metric
Halogen-free	yes
With flange	no
WAF	17
Self-locking	no
Left thread	no
Thread, imperial	3/8"
Nut version	Nut
Screw system nut	Hexagon head