


Technical data sheet

Hexagonal nut DIN 934 G

Item number: 3400107



Hexagonal nut to DIN 934 with metric thread.

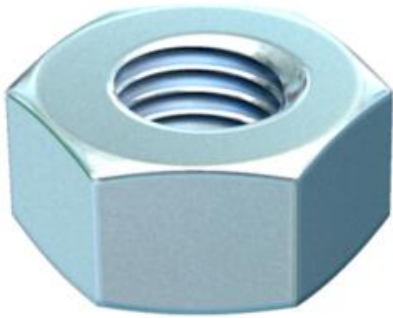

St	Steel
G	Electrogalvanized

Master data

Item number	3400107
Type	HN M10 G
Description 1	Hexagonal nut
Manufacturer	OBO
Dimension	M10
Material	Steel
Surface	Electrogalvanized
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	100
Unit of quantity	Piece
Weight	1.014 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,0283 kg COe / 1 Piece


Technical data sheet

Hexagonal nut DIN 934 G

Item number: 3400107



Dimensions

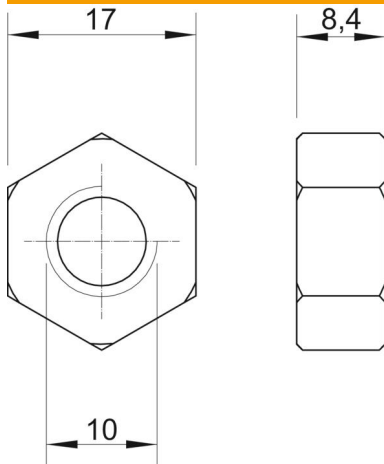

Dimension d	10 mm
Dimension h	8.4 mm

Technical data

Resistance grade	8.8
Thread	M10
Thread metric	10
Thread type	Metric
Halogen-free	yes
With flange	no
WAF	17
Self-locking	no
Left thread	no
Thread, imperial	3/8"
Nut version	Nut
Screw system nut	Hexagon head