

# Technical data sheet

## Hexagonal nut DIN 934 V4A

Item number: 3397145



Hexagonal nut to DIN 934 with metric thread.



**A4** Stainless steel

**2B** Bright, treated

### Master data

|                                   |                         |
|-----------------------------------|-------------------------|
| Item number                       | 3397145                 |
| Type                              | HN M12 A4               |
| Description 1                     | Hexagonal nut           |
| Manufacturer                      | OBO                     |
| Dimension                         | M12                     |
| Material                          | Stainless steel         |
| Surface                           | Bright, treated         |
| Surface standard                  |                         |
| Smallest sales unit               | 100                     |
| Unit of quantity                  | Piece                   |
| Weight                            | 1.73 kg                 |
| Weight unit                       | kg/100 pc.              |
| CO Footprint (GWP) Cradle-to-Gate | 0,0834 kg COe / 1 Piece |


# Technical data sheet

## Hexagonal nut DIN 934 V4A

Item number: 3397145



### Dimensions

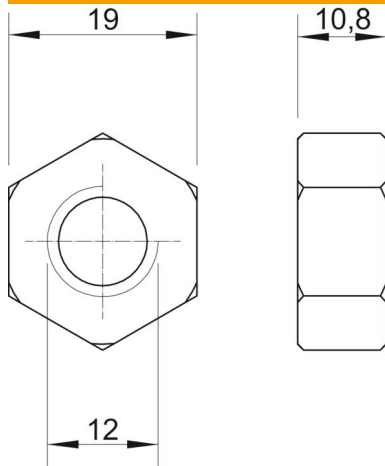

|             |         |
|-------------|---------|
| Dimension d | 12 mm   |
| Dimension h | 10.8 mm |

### Technical data

|                  |              |
|------------------|--------------|
| Resistance grade | 8            |
| Thread           | M12          |
| Thread metric    | 12           |
| Thread type      | Metric       |
| Halogen-free     | yes          |
| With flange      | no           |
| WAF              | 19           |
| Self-locking     | no           |
| Left thread      | no           |
| Thread, imperial | 1/2"         |
| Nut version      | Nut          |
| Screw system nut | Hexagon head |