

# Technical data sheet

## Service pole, type ISS110100R

Item number: 6289063



ISS aluminium service pole with a thin tube to the ceiling.

Set consists of:

1 single-compartment pole with clamping fastening

 
Total length 3,315–3,480 mm

1 clamping device for clamping to the ceiling

1 equipable aluminium installation area

Length: 780 mm

In areas for device installation, the service pole has a 76.5 mm system opening and is suitable for accepting front-locking accessory mounting boxes of the series 71GD...



**Alu** Aluminium

**EL** Anodised

### Master data

|                     |               |
|---------------------|---------------|
| Item number         | 6289063       |
| Type                | ISS110100REL  |
| Description 1       | Service pole  |
| Description 2       | floor/ceiling |
| Manufacturer        | OBO           |
| Dimension           | 3000x100x110  |
| Colour              | aluminium     |
| Material            | Aluminium     |
| Surface             | Anodised      |
| Surface standard    |               |
| Smallest sales unit | 1             |
| Unit of quantity    | Piece         |
| Weight              | 1000 kg       |
| Weight unit         | kg/100 pc.    |


# Technical data sheet

Service pole, type ISS110100R

Item number: 6289063



## Dimensions

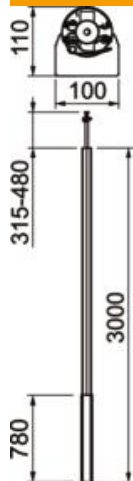

|        |          |
|--------|----------|
| Length | 3,000 mm |
| Width  | 100 mm   |
| Height | 110 mm   |

## Technical data

|                               |   |
|-------------------------------|---|
| Number of usable covers       | 1                                       |
| Number of compartments        | 1 St.                                   |
| Version for                   | Single-sided                            |
| Fastening type                | Tension                                 |
| Floor mounting                | yes                                     |
| Ceiling mounting              | yes                                     |
| Continuous profile            | no                                      |
| Halogen-free                  | yes                                     |
| Height compensation, max.     | 480 mm                                  |
| Height compensation, min.     | 315 mm                                  |
| Cable entry                   | Top/bottom                              |
| Cover width                   | 76.5 mm                                 |
| Changes according to location | no                                      |
| Pole shape                    | Installation space, angular/pole, round |
| Pole height, max.             | 3480 mm                                 |
| Pole height, min.             | 3315 mm                                 |
| Adjustable                    | yes                                     |
| Pre-wired                     | no                                      |