

Technical data sheet

Service pole, type ISS110100R

Item number: 6289060



ISS aluminium service pole with a thin tube to the ceiling.

Set consists of:

1 single-compartment pole with clamping fastening

Total length 3,315–3,480 mm

1 clamping device for clamping to the ceiling

1 equipable aluminium installation area

Length: 780 mm

In areas for device installation, the service pole has a 76.5 mm system opening and is suitable for accepting front-locking accessory mounting boxes of the series 71GD...



Alu Aluminium

Master data

Item number	6289060
Type	ISS110100RRW
Description 1	Service pole
Description 2	floor/ceiling
Manufacturer	OBO
Dimension	3000x100x110
Colour	Pure white; RAL 9010
Material	Aluminium
Smallest sales unit	1
Unit of quantity	Piece
Weight	1000 kg
Weight unit	kg/100 pc.


Technical data sheet

Service pole, type ISS110100R

Item number: 6289060



Dimensions

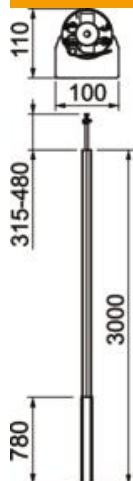

Length	3,000 mm
Width	100 mm
Height	110 mm

Technical data

Number of usable covers	1
Number of compartments	1 St.
Version for	Single-sided
Fastening type	Tension
Floor mounting	yes
Ceiling mounting	yes
Continuous profile	no
Halogen-free	yes
Height compensation, max.	480 mm
Height compensation, min.	315 mm
Cable entry	Top/bottom
Cover width	76.5 mm
Changes according to location	no
Pole shape	Installation space, angular/pole, round
Pole height, max.	3480 mm
Pole height, min.	3315 mm
Adjustable	yes
Pre-wired	no