

Technical data sheet

Service pole, type ISS70110

Item number: 6288943



ISS aluminium service pole with a 76.5 mm system opening.

Set consists of:

1 single-compartment pole with clamping fastening

Total length 3,315–3,480 mm

1 ceiling fastening with clamping device

1 aluminium cover

Length: 3,000 mm

The service pole is suitable for accepting front-locking accessory mounting boxes of the series 71GD... The installation of a partition of type GA-TW70 (6279711) and the installation of the cover clip, type KL80A (6288640), are possible as an option.

The following accessories can be used, depending on the mounting situation.



Alu	Aluminium
EL	Anodised

Master data

Item number	6288943
Type	ISS70110EL
Description 1	Service pole
Description 2	floor/ceiling
Manufacturer	OBO
Dimension	3000x110x70
Colour	aluminium
Material	Aluminium
Surface	Anodised
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	750 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	98,2663 kg CO2e / 1 Piece


Technical data sheet

Service pole, type ISS70110

Item number: 6288943



Dimensions

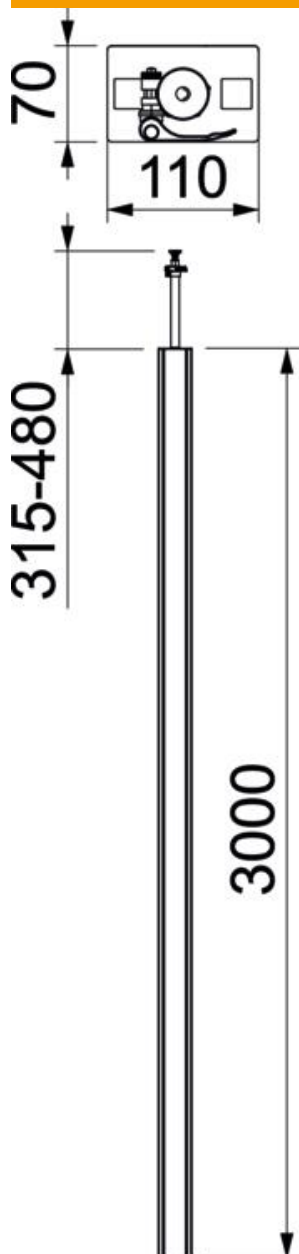

Length	3,000 mm
Width	110 mm
Height	70 mm

Technical data sheet

Service pole, type ISS70110

Item number: 6288943



Technical data

Number of usable covers	1
Number of compartments	1 St.
Version for	Single-sided
Fastening type	Tension
Floor mounting	yes
Ceiling mounting	yes
Continuous profile	yes
Halogen-free	yes
Height compensation, max.	480 mm
Height compensation, min.	315 mm
Cable entry	Top/bottom
Cover width	76.5 mm
Changes according to location	no
Pole shape	Rectangular
Pole height, max.	3480 mm
Pole height, min.	3315 mm
Adjustable	yes
Pre-wired	no