

Technical data sheet

Service pole, sheet steel, with sheet steel cover

Item number: 6286530



Sheet steel service pole with a 76.5 mm system opening.

Set consisting of:

1 single-compartment pole with clamping fastening

Total length 2,625–3,665 mm

1 ceiling fastening with telescopic profile

1 sheet steel cover

Length: 2,500 mm

A 2 m PVC separating retainer and 2 cover clips are contained in the scope of delivery.

The service pole is suitable for accepting accessory mounting boxes of the series 71GD...

The service pole is pre-mounted and ready for use immediately. The following accessories can also be used, depending on the mounting situation.



St Steel

Master data

| | |
|---------------------|----------------------------|
| Item number | 6286530 |
| Description 1 | Service pole |
| Description 2 | floor-ceiling cover, steel |
| Manufacturer | OBO |
| Dimension | 2505x115x75 |
| Colour | Pure white; RAL 9010 |
| Material | Steel |
| Smallest sales unit | 1 |
| Unit of quantity | Piece |
| Weight | 1121 kg |
| Weight unit | kg/100 pc. |


Technical data sheet

Service pole, sheet steel, with sheet steel cover

Item number: 6286530



Dimensions

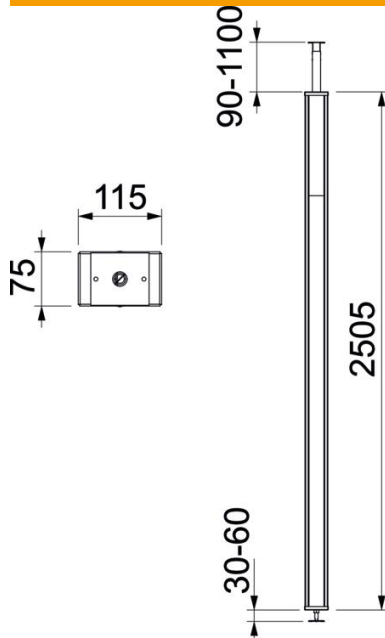

| | |
|--------|----------|
| Length | 2,505 mm |
| Width | 115 mm |
| Height | 75 mm |

Technical data

| | |
|-------------------------------|--------------|
| Number of usable covers | 1 |
| Number of compartments | 1 St. |
| Version for | Single-sided |
| Fastening type | Telescope |
| Floor mounting | no |
| Ceiling mounting | yes |
| Continuous profile | yes |
| Halogen-free | yes |
| Height compensation, max. | 1100 mm |
| Height compensation, min. | 90 mm |
| Cable entry | Top |
| Cover width | 76.5 mm |
| Changes according to location | no |
| Pole shape | Rectangular |
| Pole height, max. | 3700 mm |
| Pole height, min. | 2600 mm |
| Adjustable | yes |
| Pre-wired | no |