

# Technical data sheet

## Service pole, type ISSDHSM45

Item number: 6289982



ISS service pole made from aluminium with 45 mm system opening for the direct installation of Modul 45 switching and connection devices.

Pole consisting of:

 
1 two-compartment pole with stand

Total length 675 mm

2 aluminium covers

Length 675 mm

The design of this service pole is based on an extremely slender, oval aluminium profile, which shows a cover of the Rapid 45 device installation trunking series at both narrow ends of the oval. The 45 mm system opening is suitable for direct acceptance of Modul 45® switching and connection devices. The installation area is theoretically sufficient for 2x 14 Modul 45® devices. If Modul 45connect® is used or in the case of cabling requiring a lot of space, the number of the max. installable devices is reduced. There is the option of installing a partition, type 2371/40 (6023096).



**Alu** Aluminium

**EL** Anodised

### Master data

Item number	6289982
Description 1	Service pole
Description 2	floor
Manufacturer	OBO
Dimension	675x80x130
Colour	aluminium
Material	Aluminium
Surface	Anodised
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	281.5 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	37,7406 kg COe / 1 Piece



# Technical data sheet

Service pole, type ISSDHSM45

Item number: 6289982



## Dimensions

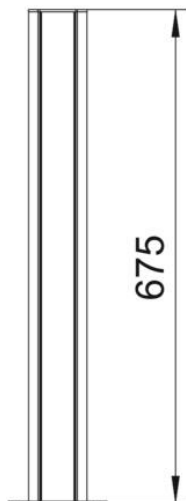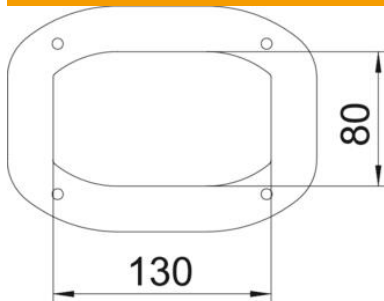

Length	675 mm
Width	80 mm
Height	130 mm

## Technical data

Number of usable covers	2
Number of compartments	2 St.
Version for	Double-sided
Fastening type	Stand
Floor mounting	yes
Ceiling mounting	no
Continuous profile	yes
Halogen-free	yes
Cable entry	Bottom
Cover width	45 mm
Changes according to location	no
Pole shape	Oval
Pole height, min.	675 mm
Adjustable	no
Pre-wired	no