

Technical data sheet

Service pole, type ISSDM45

Item number: 6289972



ISS aluminium service pole with a 45 mm system opening.

Set consists of:

1 two-compartment pole with clamping fastening

Total length 3,315–3,480 mm

1 ceiling fastening with clamping device

2 aluminium covers, length: 3,000 mm

The clamping device attached at the top of the ISS service pole can be variably adjusted between 315 and 480 mm. Possible colour options are aluminium anodised or pure white. The pole is based on a slender, oval aluminium profile.

There are two 45 mm system openings on opposite sides for direct installation of Module 45® devices.



Alu Aluminium

EL Anodised

Master data

Item number	6289972
Type	ISSDM45EL
Description 1	Service pole
Description 2	floor/ceiling
Manufacturer	OBO
Dimension	3000x80x130
Colour	aluminium
Material	Aluminium
Surface	Anodised
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	1172 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	144,2505 kg COe / 1 Piece


Technical data sheet

Service pole, type ISSDM45

Item number: 6289972



Dimensions

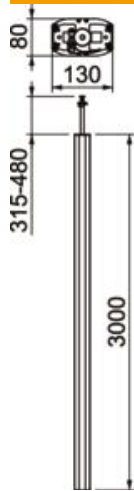

Length	3,000 mm
Width	80 mm
Height	130 mm

Technical data

Number of usable covers	2
Number of compartments	2 St.
Version for	Double-sided
Fastening type	Tension
Floor mounting	yes
Ceiling mounting	yes
Continuous profile	yes
Halogen-free	yes
Height compensation, max.	480 mm
Height compensation, min.	315 mm
Cable entry	Top/bottom
Cover width	45 mm
Changes according to location	no
Pole shape	Oval
Pole height, max.	3480 mm
Pole height, min.	3315 mm
Adjustable	yes
Pre-wired	no