

# Technical data sheet

## Service pole, type ISSDM45F

Item number: 6289974



ISS aluminium service pole with a 45 mm system opening.

Set consists of:

1 two-compartment pole with 2 flexible hoses to the ceiling

Total length of the aluminium profile: 2,300 mm

2 aluminium covers, length: 2,300 mm

The colours are either pure white or anodised. There are two 45 mm system openings on opposite sides for direct installation of Module 45® devices. The floor plate as a stand, type SFISSF, and the hose connection to the ceiling, type SAISSF, should be ordered separately (see articles below).



**Alu** Aluminium

### Master data

Item number	6289974
Description 1	Service pole
Description 2	floor/ceiling
Manufacturer	OBO
Dimension	2300x80x130
Colour	Pure white; RAL 9010
Material	Aluminium
Smallest sales unit	1
Unit of quantity	Piece
Weight	871 kg
Weight unit	kg/100 pc.


# Technical data sheet

Service pole, type ISSDM45F


Item number: 6289974



## Dimensions

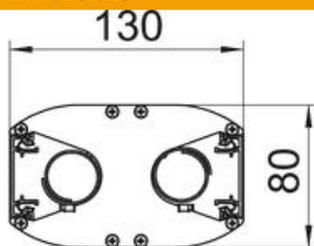

Length	2,300 mm
Width	80 mm
Height	130 mm

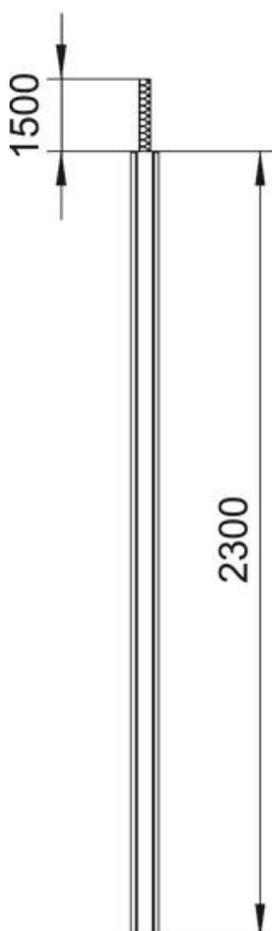

# Technical data sheet

Service pole, type ISSDM45F

Item number: 6289974



## Technical data

Number of usable covers	2
Number of compartments	2 St.
Version for	Double-sided
Fastening type	Stand
Floor mounting	yes
Ceiling mounting	yes
Continuous profile	yes
Halogen-free	yes
Height compensation, max.	1500 mm
Height compensation, min.	0 mm
Cable entry	Top
Cover width	45 mm
Changes according to location	yes
Pole shape	Oval
Pole height, max.	3800 mm
Pole height, min.	2300 mm
Adjustable	yes
Pre-wired	no