

Technical data sheet

Service pole, type ISSHS140250

Item number: 6290023

 


ISS aluminium service pole, 2-compartment, with a 76.5 mm system opening.

Empty, equippable with standard devices (socket, telephone, etc.), max. 4 devices.

Fixing possible directly on floor. Accessory mounting boxes to be ordered separately.

The service pole is suitable for accepting front-locking accessory mounting boxes of the series 71GD.... The installation of a partition of type GA-TW (6279711) and the installation of the cover clip, type KL80A, are possible as an option.



Alu Aluminium

EL Anodised

Master data

Item number	6290023
Type	ISSHS140250EL
Description 1	Service pole
Description 2	floor
Manufacturer	OBO
Dimension	250x130x140
Colour	aluminium
Material	Aluminium
Surface	Anodised
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	175 kg
Weight unit	kg/100 pc.



Technical data sheet

Service pole, type ISSHS140250

Item number: 6290023



Dimensions

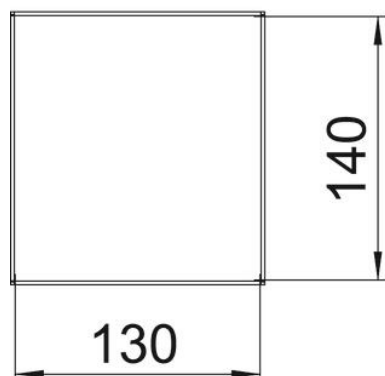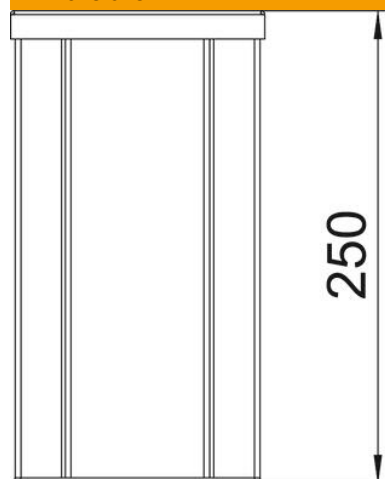

Length	250 mm
Width	130 mm
Height	140 mm

Technical data

Number of usable covers	2
Number of compartments	2 St.
Version for	Double-sided
Fastening type	Bolts
Floor mounting	yes
Ceiling mounting	no
Continuous profile	yes
Halogen-free	yes
Cable entry	Bottom
Cover width	76.5 mm
Changes according to location	no
Pole shape	Rectangular
Pole height, min.	250 mm
Adjustable	no
Pre-wired	no