

Technical data sheet

Service pole, type ISSHS140700

Item number: 6290043



 
ISS aluminium service pole, 2-compartment, with a 76.5 mm system opening.

Empty, equippable with standard devices (socket, telephone, etc.), max. 10 devices.

Direct fastening on floor possible. Accessory mounting boxes to be ordered separately.

The service pole is suitable for accepting front locking accessory mounting boxes of the

series 71GD.... The installation of a partition of type GA-TW (6279711) and the installation of the cover clip, type KL80A, are possible as an option.



Alu Aluminium

EL Anodised

Master data

Item number	6290043
Description 1	Service pole
Description 2	floor
Manufacturer	OBO
Dimension	675x130x140
Colour	aluminium
Material	Aluminium
Surface	Anodised
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	466 kg
Weight unit	kg/100 pc.


Technical data sheet

Service pole, type ISSHS140700


Item number: 6290043



Dimensions

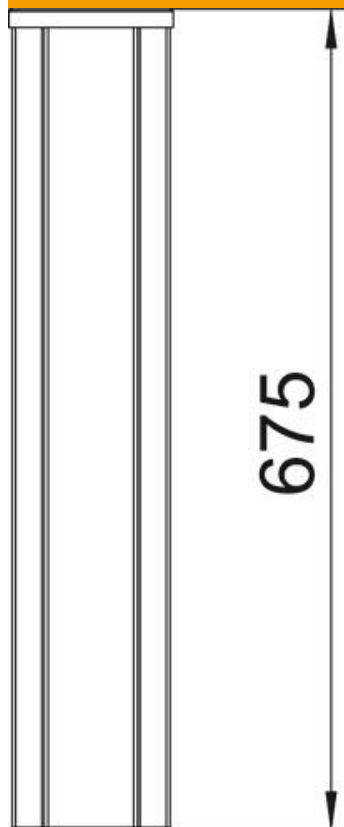

Length	675 mm
Width	130 mm
Height	140 mm

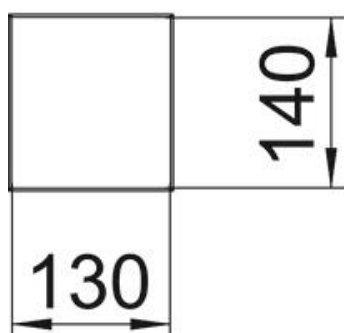

Technical data sheet

Service pole, type ISSHS140700

Item number: 6290043



Technical data

Number of usable covers	2
Number of compartments	2 St.
Version for	Double-sided
Fastening type	Bolts
Floor mounting	yes
Ceiling mounting	no
Continuous profile	yes
Halogen-free	yes
Cable entry	Bottom
Cover width	76.5 mm
Changes according to location	no
Pole shape	Rectangular
Pole height, min.	675 mm
Adjustable	no
Pre-wired	no