

Technical data sheet

Service pole, type ISSHS6

 
Item number: 6290073



ISS service pole centre.

Empty, can be equipped from all four sides with standard devices (socket, telephone, etc.). Two sides of the installation centre can be equipped in two compartments, the other two sides in one. Each installation compartment can accept 5 devices, the entire installation centre accepts max. 30 devices. Direct fastening on floor possible. Accessory mounting boxes to be ordered separately.

The service pole is suitable for accepting front locking accessory mounting boxes of the series 71GD.... The installation of a partition of type GA-TW (6279711) and the installation of the cover clip, type KL80A, are possible as an option.



- Alu Aluminium
- EL Anodised

Master data	
Item number	6290073
Description 1	Service post centre
Manufacturer	OBO
Dimension	564x290x260
Colour	aluminium
Material	Aluminium
Surface	Anodised
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	720 kg
Weight unit	kg/100 pc.


Technical data sheet

Service pole, type ISSHS6

Item number: 6290073



Dimensions

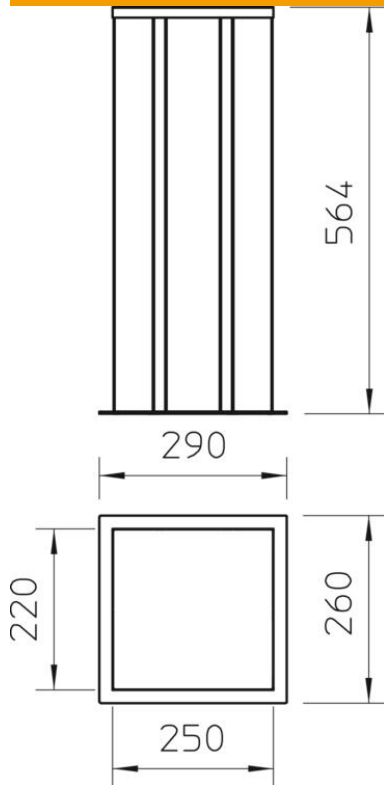

Length	564 mm
Width	290 mm
Height	260 mm

Technical data

Number of usable covers	6
Number of compartments	6 St.
Version for	Miscellaneous
Fastening type	Bolts
Floor mounting	yes
Ceiling mounting	no
Continuous profile	yes
Halogen-free	yes
Cable entry	Bottom
Cover width	76.5 mm
Changes according to location	no
Pole shape	Rectangular
Pole height, min.	564 mm
Adjustable	no
Pre-wired	no