


Technical data sheet

Panel 355 mm for ISSMKS

Item number: 6286766

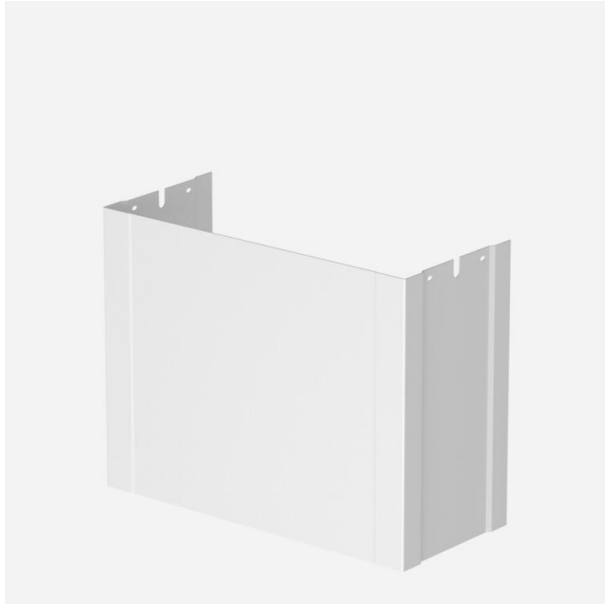

Height compensation panel for variable height adjustment. Hides the distance between the media pole and the ceiling. Suitable for a room height of 2,985 mm to 3,150 mm.



St	Steel
P	Powder-coated

Master data

Item number	6286766
Type	ISSMKS BL RW 355
Description 1	Height compensation panel
Description 2	for ISSMKS
Manufacturer	OBO
Dimension	355x461x201
Colour	Pure white; RAL 9010
Material	Steel
Surface	Powder-coated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	359.6 kg
Weight unit	kg/100 pc.


Technical data sheet

Panel 355 mm for ISSMKS

Item number: 6286766



Dimensions

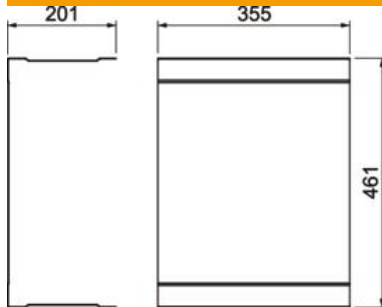

Length	355 mm
Width	461 mm
Height	201 mm

Technical data

Type of accessory	Miscellaneous
Fastening type	Bolts
Halogen-free	yes
Height compensation, min.	165 mm
Protection rating	IP20
Protection rating IK code	IK10
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C