

# Technical data sheet

Service pole, type ISSOG70140

Item number: 6289088



ISS service pole, oval shape, aluminium, with a 76.5 mm system opening.

Set consists of:

1 single-compartment column with clamping attachment

Total length: 3,315–3,480 mm

1 single-compartment pole with clamping device

1 trunking installation profile

Length 3,000 mm

1 aluminium cover

Length: 3,000 mm

The area for device installation is suitable for accepting front-locking accessory mounting boxes of the series 71GD...

The following accessories can be used, depending on the mounting situation.



Alu	Aluminium
EL	Anodised

## Master data

Item number	6289088
Type	ISSOG70140EL
Description 1	Service pole
Description 2	Floor/ceiling
Manufacturer	OBO
Dimension	3000x146x65
Colour	aluminium
Material	Aluminium
Surface	Anodised
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	700 kg
Weight unit	kg/100 pc.


# Technical data sheet

Service pole, type ISSOG70140

Item number: 6289088



## Dimensions

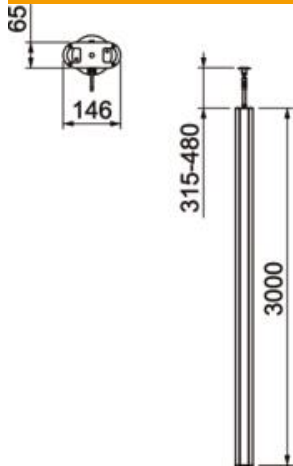

Length	3,000 mm
Width	146 mm
Height	65 mm

## Technical data

Number of usable covers	1
Number of compartments	1 St.
Version for	Single-sided
Fastening type	Tension
Floor mounting	yes
Ceiling mounting	yes
Continuous profile	yes
Halogen-free	yes
Height compensation, max.	480 mm
Height compensation, min.	315 mm
Cable entry	Top/bottom
Cover width	76.5 mm
Changes according to location	no
Pole shape	Oval
Pole height, max.	3480 mm
Pole height, min.	3315 mm
Adjustable	yes
Pre-wired	no