

Technical data sheet

Service pole, type ISSRM45F

Item number: 6290097



ISS aluminium service pole with a flexible hose to the ceiling and a 45 mm system opening.

Set consisting of:

1 one-compartment pole with flexible hose to ceiling

Total length: 2,300 mm

1 flexible hose, length: 1,500 mm

1 aluminium cover

Length: 2,300 mm

The design of this ISS service pole is based on an extremely slender, round aluminium profile, which has a smooth cover of the Rapid 45 device installation trunking series as its front side. The 45 mm system opening is suitable for direct acceptance of Modul 45® switching and connection devices.

The floor plate as a stand, type SFISSE, and the hose connection to the ceiling, type SAISSE, should be ordered separately (see articles below).



Alu Aluminium

EL Anodised

Master data

Item number	6290097
Type	ISSRM45FEL
Description 1	Service pole
Description 2	floor/ceiling tube HT
Manufacturer	OBO
Dimension	2300x70x59
Colour	aluminium
Material	Aluminium
Surface	Anodised
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	380 kg
Weight unit	kg/100 pc.


Technical data sheet

Service pole, type ISSRM45F

Item number: 6290097



Dimensions

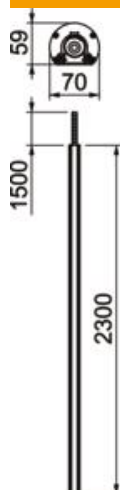

Length	2,300 mm
Width	70 mm
Height	59 mm

Technical data

Number of usable covers	1
Number of compartments	1 St.
Version for	Single-sided
Fastening type	Stand
Floor mounting	yes
Ceiling mounting	yes
Continuous profile	yes
Halogen-free	yes
Height compensation, max.	1500 mm
Height compensation, min.	0 mm
Cable entry	Top
Cover width	45 mm
Changes according to location	yes
Pole shape	Round
Pole height, max.	3800 mm
Pole height, min.	2300 mm
Adjustable	yes
Pre-wired	no