

# Technical data sheet

## Service pole, type ISSRM45F

Item number: 6290095



ISS aluminium service pole with a flexible hose to the ceiling and a 45 mm system opening.

Set consisting of:

1 one-compartment pole with flexible hose to ceiling

Total length: 2,300 mm

1 flexible hose, length: 1,500 mm

1 aluminium cover

Length: 2,300 mm

The design of this ISS service pole is based on an extremely slender, round aluminium profile, which has a smooth cover of the Rapid 45 device installation trunking series as its front side. The 45 mm system opening is suitable for direct acceptance of Modul 45® switching and connection devices.

The floor plate as a stand, type SFISSE, and the hose connection to the ceiling, type SAISSE, should be ordered separately (see articles below).



**Alu** Aluminium

### Master data

|                     |                       |
|---------------------|-----------------------|
| Item number         | 6290095               |
| Description 1       | Service pole          |
| Description 2       | floor/ceiling tube HT |
| Manufacturer        | OBO                   |
| Dimension           | 2300x70x59            |
| Colour              | Pure white; RAL 9010  |
| Material            | Aluminium             |
| Smallest sales unit | 1                     |
| Unit of quantity    | Piece                 |
| Weight              | 380 kg                |
| Weight unit         | kg/100 pc.            |


# Technical data sheet

## Service pole, type ISSRM45F

Item number: 6290095



### Dimensions

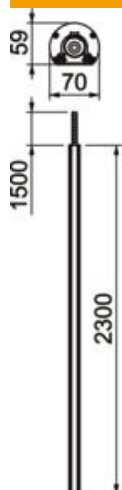

|        |          |
|--------|----------|
| Length | 2,300 mm |
| Width  | 70 mm    |
| Height | 59 mm    |

### Technical data

|                               |              |
|-------------------------------|--------------|
| Number of usable covers       | 1            |
| Number of compartments        | 1 St.        |
| Version for                   | Single-sided |
| Fastening type                | Stand        |
| Floor mounting                | yes          |
| Ceiling mounting              | yes          |
| Continuous profile            | yes          |
| Halogen-free                  | yes          |
| Height compensation, max.     | 1500 mm      |
| Height compensation, min.     | 0 mm         |
| Cable entry                   | Top          |
| Cover width                   | 45 mm        |
| Changes according to location | yes          |
| Pole shape                    | Round        |
| Pole height, max.             | 3800 mm      |
| Pole height, min.             | 2300 mm      |
| Adjustable                    | yes          |
| Pre-wired                     | no           |