

# Technical data sheet

## Service pole, type ISSRM45

Item number: 6290086



ISS aluminium service pole with a 45 mm system opening.

Set consists of:

1 one-compartment pole with clamping fastening

Total length: 3,315 mm–3,480 mm

1 ceiling attachment with clamping device

1 aluminium cover

Length: 3,000 mm

The design of this ISS service pole is based on an extremely slender, round aluminium profile, which has a smooth cover of the Rapid 45 device installation trunking series as its front side. The 45 mm system opening is suitable for direct acceptance of Modul 45® switching and connection devices.



**Alu** Aluminium

### Master data

|                     |                      |
|---------------------|----------------------|
| Item number         | 6290086              |
| Description 1       | Service pole         |
| Description 2       | floor/ceiling        |
| Manufacturer        | OBO                  |
| Dimension           | 3000x70x59           |
| Colour              | Pure white; RAL 9010 |
| Material            | Aluminium            |
| Smallest sales unit | 1                    |
| Unit of quantity    | Piece                |
| Weight              | 510 kg               |
| Weight unit         | kg/100 pc.           |


# Technical data sheet

## Service pole, type ISSRM45

Item number: 6290086



### Dimensions

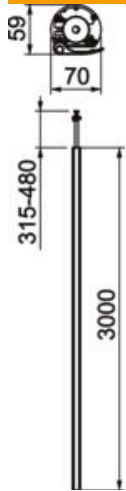

|        |          |
|--------|----------|
| Length | 3,000 mm |
| Width  | 70 mm    |
| Height | 59 mm    |

### Technical data

|                               |              |
|-------------------------------|--------------|
| Number of usable covers       | 1            |
| Number of compartments        | 1 St.        |
| Version for                   | Single-sided |
| Fastening type                | Tension      |
| Floor mounting                | yes          |
| Ceiling mounting              | yes          |
| Continuous profile            | yes          |
| Halogen-free                  | yes          |
| Height compensation, max.     | 480 mm       |
| Height compensation, min.     | 315 mm       |
| Cable entry                   | Top          |
| Cover width                   | 45 mm        |
| Changes according to location | no           |
| Pole shape                    | Round        |
| Pole height, max.             | 3480 mm      |
| Pole height, min.             | 3315 mm      |
| Adjustable                    | yes          |
| Pre-wired                     | no           |