


Technical data sheet

Cable outlet for 3–11 mm cross-section, aluminium-painted

Item number: 6117422

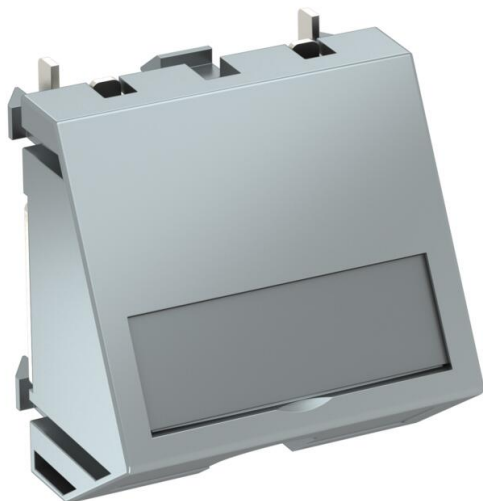

Two-part cable outlet with labelling panel, consisting of a cable support with strain relief and a cover. The strain relief is suited for cable cross-sections of 3 to 11 mm. The locking fastening is suitable for horizontal and vertical installation in the system environment.

PC Polycarbonate

Master data

| | |
|---------------------|--------------------|
| Item number | 6117422 |
| Description 1 | Cable outlet |
| Description 2 | with strain relief |
| Manufacturer | OBO |
| Dimension | 45x45mm |
| Colour | Aluminium painted |
| Material | Polycarbonate |
| Smallest sales unit | 1 |
| Unit of quantity | Piece |
| Weight | 3.5 kg |
| Weight unit | kg/100 pc. |


Technical data sheet

Cable outlet for 3–11 mm cross-section, aluminium-painted

Item number: 6117422



Dimensions

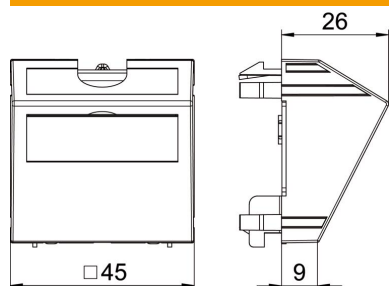

| | |
|--------|-------|
| Width | 45 mm |
| Height | 45 mm |

Technical data

| | |
|--|-------------------------|
| Number of units | 1 |
| Surface version | Matt |
| Fastening type | Clamp fastening |
| Flush-mounted version | yes |
| Suitable for built-in installations | no |
| Suitable for device installation ducts | yes |
| Suitable for underfloor duct socket | no |
| Suitable for flush-mounted installations | no |
| Halogen-free | yes |
| Hinged cover | no |
| Mounting direction | Horizontal and vertical |
| Text field/inscription field | yes |
| Depth | 26 mm |
| Transparent | no |