

# Technical data sheet

## Body-bound rivet, KSN 22

Item number: 6178525



The KNW2 riveting tool should be used for rapid mounting and for the optimum function. Dimension of the drill hole: 6.5 mm.

Total clamping strength: 2.8 – 6 mm



PA

Polyamide

### Master data

|                     |                      |
|---------------------|----------------------|
| Item number         | 6178525              |
| Type                | KSN22                |
| Description 1       | Body-bound rivet     |
| Description 2       | size 2               |
| Manufacturer        | OBO                  |
| Dimension           | Ø6,3mm               |
| Colour              | Light grey; RAL 7035 |
| Material            | Polyamide            |
| Smallest sales unit | 100                  |
| Unit of quantity    | Piece                |
| Weight              | 0.07 kg              |
| Weight unit         | kg/100 pc.           |


# Technical data sheet

## Body-bound rivet, KSN 22

Item number: 6178525



### Dimensions

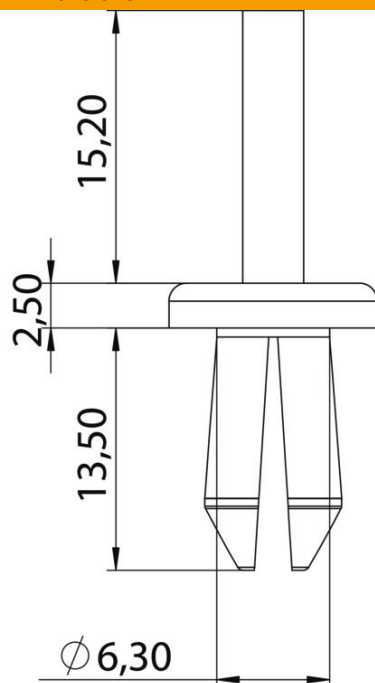

|             |        |
|-------------|--------|
| Dimension a | 6.3 mm |
|-------------|--------|

### Technical data

|                    |        |
|--------------------|--------|
| Bore hole diameter | 6.5 mm |
| Halogen-free       | yes    |