

Technical data sheet

Magic straight connector set A4

Item number: 6068988



Cable tray connector with quick fastening for the screwless connection of perforated cable trays with a side height of 60 mm.
The optimised design means that the connector can be used to create radii and as a length compensation piece for large temperature deviations.



A4 Stainless steel

2B Bright, treated

Master data

| | |
|---------------------|------------------------|
| Item number | 6068988 |
| Description 1 | Straight connector set |
| Description 2 | for cable tray Magic |
| Manufacturer | OBO |
| Dimension | 60x400x200 |
| Colour | stainless steel |
| Material | Stainless steel |
| Surface | Bright, treated |
| Surface standard | |
| Smallest sales unit | 1 |
| Unit of quantity | Piece |
| Weight | 50.7 kg |
| Weight unit | kg/100 pc. |


Technical data sheet

Magic straight connector set A4

Item number: 6068988



Dimensions

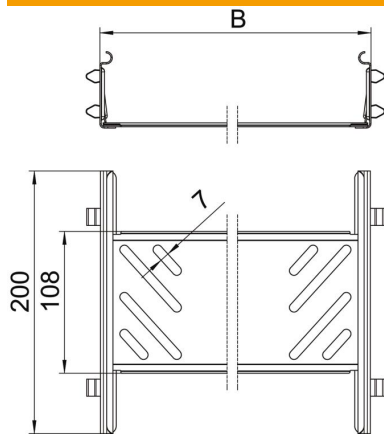

| | |
|-----------------|--------|
| Dimension | 60x400 |
| Length | 200 mm |
| Width | 400 mm |
| Height | 60 mm |
| Plate thickness | 1 mm |
| Dimension B | 400 mm |

Technical data

| | |
|---------------------------------------|---------------------|
| Version for | Straight connector |
| Maintain electrical functions | no |
| Suitable for mesh cable tray | no |
| Suitable for cable ladder | no |
| Suitable for cable tray | yes |
| Suitable for cable tray system height | 60 mm |
| Adjustable connector, horizontal | no |
| Articulated connector, vertical | no |
| Rustproof steel, pickled | no |
| Connection type | Screwless connector |