


Technical data sheet

Magic straight connector set DD

Item number: 6069030



Cable tray connector with quick fastening for the screwless connection of perforated cable trays with a side height of 85 mm.
The optimised design means that the connector can be used to create radii and as a length compensation piece for large temperature deviations.

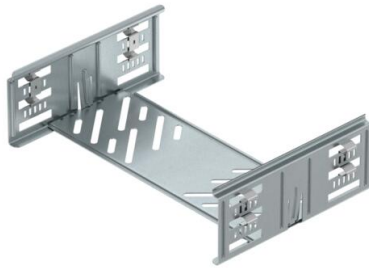

St

Steel

DD

Strip galvanised zinc/aluminium, Double Dip

Master data

Item number	6069030
Type	KTSMV 830 DD
Description 1	Straight connector set
Description 2	for cable tray Magic
Manufacturer	OBO
Dimension	85x300x200
Colour	zinc
Material	Steel
Surface	Strip galvanised zinc/aluminium, Double Dip
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	50.6 kg
Weight unit	kg/100 pc.


Technical data sheet

Magic straight connector set DD


Item number: 6069030



Dimensions

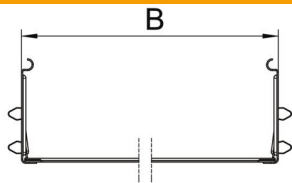

Dimension	85x300
Length	200 mm
Width	300 mm
Height	85 mm
Plate thickness	1 mm
Dimension B	300 mm

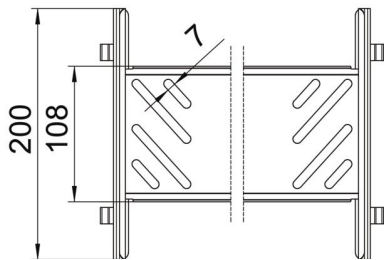

Technical data

Version for	Straight connector
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Suitable for cable tray system height	85 mm
Adjustable connector, horizontal	no
Articulated connector, vertical	no
Rustproof steel, pickled	no
Connection type	Screwless connector