

Technical data sheet


Coupling KUPP

Item number: 6288680



Coupling for connecting the trunking bases. This creates the equipotential bonding between the trunking bases.

The scope of delivery of a coupling includes 2 connection plates.

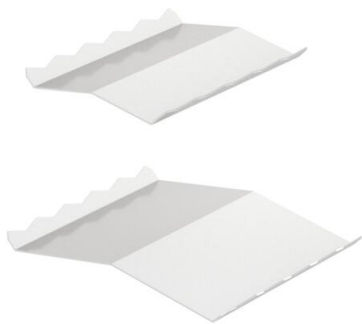

A2 Stainless steel

Master data	
Item number	6288680
Description 1	Coupling
Description 2	for desk trunking
Manufacturer	OBO
Dimension	133x105
Colour	stainless steel
Material	Stainless steel
Smallest sales unit	1
Unit of quantity	Piece
Weight	14.8 kg
Weight unit	kg/100 pc.


Technical data sheet

Coupling KUPP

Item number: 6288680



Dimensions

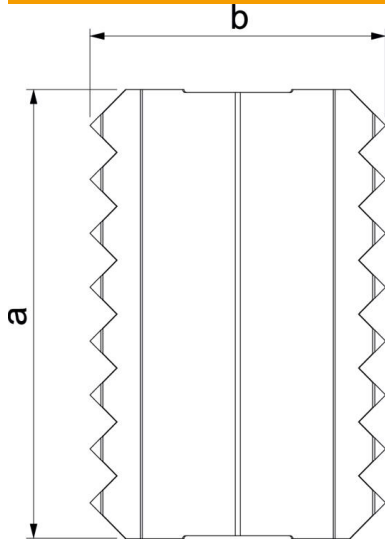

Length	133 mm
Width	105 mm
Dimension a	105 mm
Dimension b	133 mm

Technical data

Version for	Universal
Type	coupling
Halogen-free	yes
Trunking depth	133 mm
With equipotential bonding	yes
Protection rating	IP30
Protection rating IK code	IK10
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C