

Technical data sheet

Head plate US 5 NOK FT

Item number: 6348939



Head plate with U support mounting rotated 90°.
When installing the head plate, please use the spacer, type DSK 45.



St	Steel
FT	Hot-dip galvanised

Master data

Item number	6348939
Description 1	Head plate
Description 2	US5 support turned through 90°
Manufacturer	OBO
Dimension	140x75x104
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	75 kg
Weight unit	kg/100 pc.



Technical data sheet

Head plate US 5 NOK FT

Item number: 6348939



Dimensions

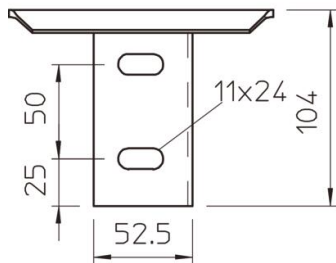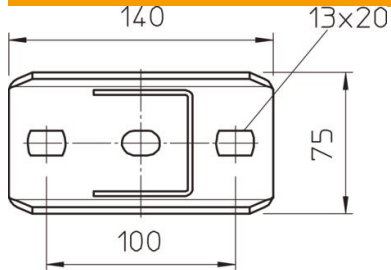

Length	140 mm
Width	75 mm
Height	104 mm

Technical data

Version for	Screw head plate
Maintain electrical functions	no
Suitable for ceiling fastening	yes
Suitable for panel fastening	no
Suitable for profile shapes	U profile
Rustproof steel, pickled	no
Angle range, max.	90 mm
Angle range, min.	90 mm