

# Technical data sheet

## Head plate, variable FT

Item number: 6348920



Variable head plate for mounting on US 5 supports. In combination with the US 5 support, suspended supports of any length can be created in situ. With the variable head plate, slopes of up to 30° can be compensated. The spacer, type DSK 47, is used for stabilisation when mounting the head plate. The maximum angle adjustment is approx. 30° on one side. Scope of delivery without bolts, type SKS 10 x 80 and spacer, type DSK 47.



St	Steel
FT	Hot-dip galvanised

### Master data

Item number	6348920
Description 1	Head plate
Description 2	for US 5 support, variable
Manufacturer	OBO
Dimension	180x59x109
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	82 kg
Weight unit	kg/100 pc.


# Technical data sheet

## Head plate, variable FT

Item number: 6348920



### Dimensions

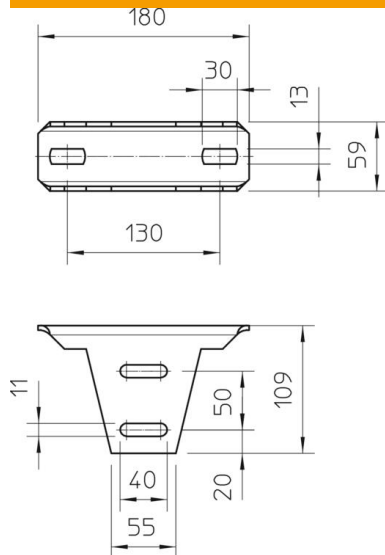

Length	180 mm
Width	59 mm
Height	109 mm

### Technical data

Version for	Screw head plate
Maintain electrical functions	no
Suitable for ceiling fastening	yes
Suitable for panel fastening	no
Suitable for profile shapes	U profile
Rustproof steel, pickled	no
Angle range, max.	30 mm
Angle range, min.	0 mm