

Technical data sheet

Mesh cable tray connector A2

Item number: 6016367



Screwed version of joint connector for mesh cable trays.
Including screw of type FRS M6 x 20.



A2 Stainless steel

2B Bright, treated

Master data

Item number	6016367
Type	K 11 262 A2
Description 1	Side connector
Description 2	for mesh cable tray
Manufacturer	OBO
Dimension	60x40
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	25
Unit of quantity	Piece
Weight	7.5 kg
Weight unit	kg/100 pc.



Technical data sheet

Mesh cable tray connector A2

Item number: 6016367



Dimensions

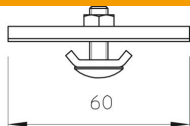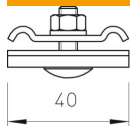

Dimension	60 x 40
Length	60 mm
Width	40 mm
Width	1.57 in
Height	24 mm
Height	0.94 in

Technical data

Version for	Straight connector
Maintain electrical functions	no
Suitable for mesh cable tray	yes
Suitable for cable ladder	no
Suitable for cable tray	no
Adjustable connector, horizontal	no
Articulated connector, vertical	no
Suitable for mesh cable tray wire, max.	4.9 mm
Suitable for mesh cable tray wire, min.	3.9 mm
Rustproof steel, pickled	yes
Connection type	Screw connector