

# Technical data sheet

## Counter plate FT

Item number: 6348440



Counter plate to increase the contact surface for pass-through installation of brackets and supports.




|    |                    |
|----|--------------------|
| St | Steel              |
| FT | Hot-dip galvanised |

### Master data

|                     |                    |
|---------------------|--------------------|
| Item number         | 6348440            |
| Type                | K 70 FT            |
| Description 1       | Lock plate         |
| Manufacturer        | OBO                |
| Dimension           | 70x70              |
| Colour              | zinc               |
| Material            | Steel              |
| Surface             | Hot-dip galvanised |
| Surface standard    | DIN EN ISO 1461    |
| Smallest sales unit | 10                 |
| Unit of quantity    | Piece              |
| Weight              | 24 kg              |
| Weight unit         | kg/100 pc.         |

### Dimensions

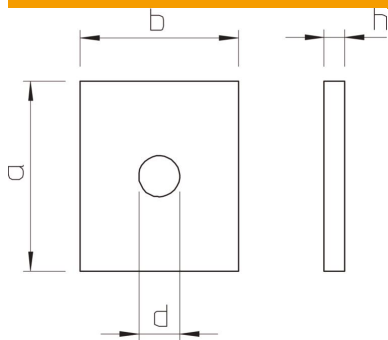

|                 |         |
|-----------------|---------|
| Plate thickness | 0.26 in |
| Dimension a     | 70 mm   |
| Dimension b     | 70 mm   |
| Dimension d     | 0.67 in |
| Dimension d     | 17 mm   |
| Dimension h     | 6.5 mm  |

# Technical data sheet

## Counter plate FT

Item number: 6348440



### Technical data

|                    |        |
|--------------------|--------|
| Inner diameter     | 17 mm  |
| Hole diameter      | 17 mm  |
| Material thickness | 6.5 mm |
| With tothing       | no     |