


# Technical data sheet

Cover for 90° bend FT

Item number: 6226020



Cover with turn buckles for covering 90° cable ladder bends with welded rungs.

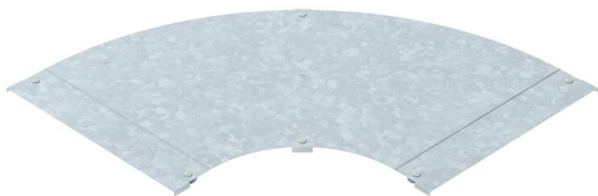

St

Steel

FT

Hot-dip galvanised

| Master data         |                    |
|---------------------|--------------------|
| Item number         | 6226020            |
| Description 1       | 90° bend cover     |
| Description 2       | with turn buckle   |
| Manufacturer        | OBO                |
| Dimension           | B600               |
| Colour              | zinc               |
| Material            | Steel              |
| Surface             | Hot-dip galvanised |
| Surface standard    | DIN EN ISO 1461    |
| Smallest sales unit | 1                  |
| Unit of quantity    | Piece              |
| Weight              | 755 kg             |
| Weight unit         | kg/100 pc.         |


# Technical data sheet

## Cover for 90° bend FT

Item number: 6226020



### Dimensions

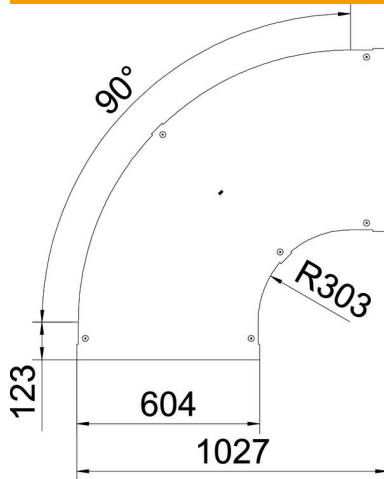

|                 |         |
|-----------------|---------|
| Width           | 600 mm  |
| Plate thickness | 1.25 mm |
| Dimension B     | 600 mm  |

### Technical data

|                               |            |
|-------------------------------|------------|
| Bend (angle)                  | 90°        |
| Fastening type                | Sash lock  |
| Maintain electrical functions | no         |
| Suitable for mesh cable tray  | no         |
| Suitable for cable ladder     | yes        |
| Suitable for cable tray       | no         |
| Change of direction           | Horizontal |
| Rustproof steel, pickled      | no         |
| Hinged                        | no         |