

Technical data sheet

90° bend VS 60 A2

Item number: 7160089



90° bend, horizontal, for cable ladders with VS rungs and a side height of 60 mm. Connectors should be ordered separately and in the appropriate quantity.




A2 Stainless steel

2B Bright, treated

Master data

Item number	7160089
Description 1	90° bend
Description 2	for cable ladder with VS rung
Manufacturer	OBO
Dimension	60x500
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	554.9 kg
Weight unit	kg/100 pc.

Dimensions

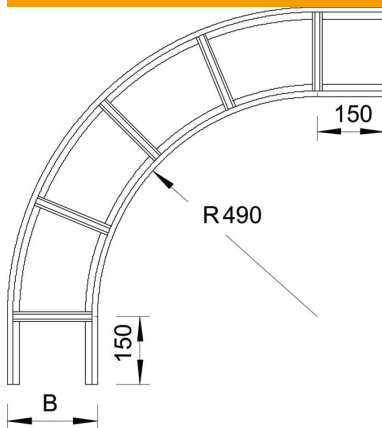

Width	500 mm
Height	60 mm

Technical data sheet

90° bend VS 60 A2

Item number: 7160089



Technical data

Bend (angle)	90°
Version of the rungs	Profile unperforated
Side rail version	Flat profile
Maintain electrical functions	no
Change of direction	Horizontal
Rustproof steel, pickled	no
Hinged	no
Side perforation	no
Wide-span version	no